


Hood NECV-S1W37

Part number: 545974

FESTO

For valve manifolds VTSA and VTSA-F, for in-house assembly without cables.

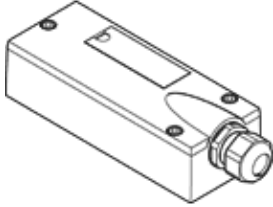

Data sheet

Feature	Value
Area of application	Only for multi-pin plug connection valve terminal VTSA/VTSA-F
Product weight	180 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Plug socket
Electrical connection 1, cable outlet	Angled
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	37
Electrical connection 1, occupied pins/wires	37
Electrical connection 1, type of mounting	3x M4 screws
Electrical connection 2, connection technology	Crimp contacts
Operating voltage range DC	0 ... 30 V
Acceptable current load at 40°C	2 A
Surge strength	1 kV
Cable gland connection	M20x1,5
Cable diameter	5 ... 13 mm
Nominal conductor cross-section	0.08 ... 0.5 mm ²
Protection class	IP65 NEMA 4
Note on degree of protection	in assembled condition
Ambient temperature	-5 ... 50 °C
PWIS conformity	VDMA24364-B1/B2-L
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material housing	PA