

 

# Solenoid valve

## MOFHB-3-3/4

Part number: 546045  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2018. See Support Portal for alternative products.

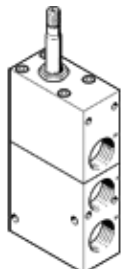

## Data sheet

Feature	Value
Valve function	3/2 open, monostable
Type of actuation	electrical
Standard nominal flow rate	5,170 l/min
Working pressure	1 ... 8 bar
Design structure	Poppet seat
Type of reset	mechanical spring
Protection class	IP65
Nominal size	17 mm
Assembly position	Any
Manual override	detenting
Switching time off	100 ms
Switching time on	70 ms
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Medium temperature	-10 ... 60 °C
Ambient temperature	-5 ... 40 °C
Product weight	830 g
Pilot exhaust port 84	M5
Pneumatic connection, port 1	G3/4
Pneumatic connection, port 2	G3/4
Pneumatic connection, port 3	G3/4
Materials information for seals	NBR
Materials information, housing	Aluminum Anodized