


# Distributor FCK-3-PK-4-N

Part number: 546066

FESTO

[Metal version.](#)

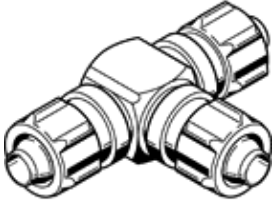

## Data sheet

Feature	Value
Nominal size	3 mm
Assembly position	Any
Operating pressure complete temperature range	0 ... 10 bar
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Product weight	10 g
Pneumatic connection, port 1	for barbed connector internal diameter 4 mm with nut
Pneumatic connection, port 2	for barbed connector internal diameter 3 mm with nut
Material housing	Wrought Aluminum alloy