

X-fitting


NPFB-X-R18-3G18-MFFF

Part number: 547783

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminum AL 99.5 can also be used.

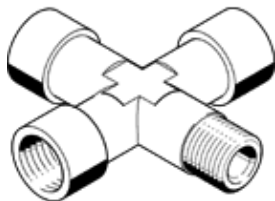

Data sheet

Feature	Value
Material information for threaded fitting	Brass Nickel plated
Container size	10
Working pressure	-0.95 ... 40 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:~:]
Corrosion resistance classification CRC	1
Ambient temperature	-20 ... 150 °C
Product weight	52 g
Pneumatic connection, port 1	R1/8
Pneumatic connection, port 2	G1/8
Materials note	Conforms to RoHS