


Extension NPFB-E3-2G18-FM

Part number: 547828

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminum AL 99.5 can also be used.

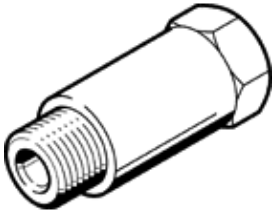

Data sheet

| Feature | Value |
|---|---|
| Material information for threaded fitting | Brass Nickel plated |
| Container size | 10 |
| Working pressure | -0.95 ... 40 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [-:~:] |
| Corrosion resistance classification CRC | 1 |
| Ambient temperature | -20 ... 150 °C |
| Product weight | 32 g |
| Pneumatic connection, port 1 | G1/8 |
| Materials note | Conforms to RoHS |