


Cover VAEM-S6-C-S6-R5

Part number: 549048

FESTO

Up to 12 single pilot valves or 6 bistable valves can be connected.

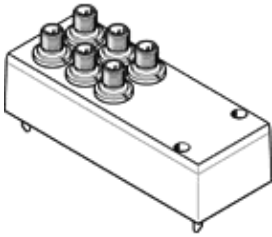

Data sheet

| Feature | Value |
|---|---|
| Max. number of valve positions | 12 with monostable valves 6 with bistable valves |
| Max. residual current | 10 A |
| Nominal operating voltage DC | 24 V |
| Permissible voltage fluctuation | +/- 10 % |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Protection class | IP65 NEMA 4 |
| Ambient temperature | -5 ... 50 °C |
| Product weight | 200 g |
| Number of electrical connections | 6 |
| Electrical connection | 5-pin M12 Plug |
| Material housing | PA |