


Axial kit EAMM-A-F80-80G

Part number: 550951

FESTO

Suitable for electric drives.

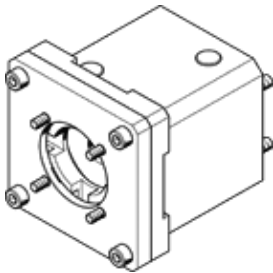

Data sheet

Feature	Value
Assembly position	Any
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	87 Nm
Product weight	2,810 g
Interface code, actuator	F80
Interface code, motor in	80G
Materials note	Conforms to RoHS