


# Axial kit

## EAMM-A-F32-87A

Part number: 550960

FESTO

Suitable for electric drives.

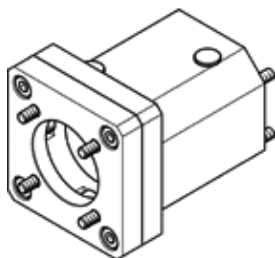

### Data sheet

| Feature                  | Value            |
|--------------------------|------------------|
| Assembly position        | Any              |
| Storage temperature      | -25 ... 60 °C    |
| Relative air humidity    | 0 - 95 %         |
| Protection class         | IP40             |
| Ambient temperature      | -10 ... 60 °C    |
| Transferable torque      | 21 Nm            |
| Product weight           | 770 g            |
| Interface code, actuator | F32              |
| Interface code, motor in | 87A              |
| Materials note           | Conforms to RoHS |