


# Axial kit EAMM-A-D40-70A

Part number: 550981

FESTO

Suitable for electric drives.

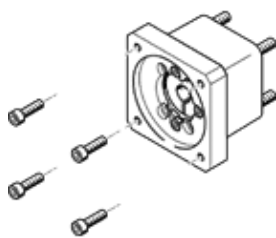

## Data sheet

Feature	Value
Assembly position	Any
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Transferable torque	12.5 Nm
Product weight	410 g
Interface code, actuator	D40A D40B D40C
Interface code, motor in	70A
Materials note	Conforms to RoHS