


Axial kit EAMM-A-D60-100A

Part number: 550983

★ Core product range

Suitable for electric drives.

FESTO

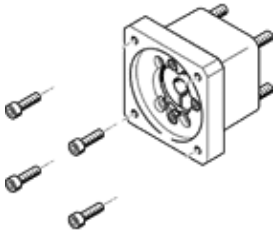

Data sheet

| Feature | Value |
|--------------------------|----------------------|
| Assembly position | Any |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP40 |
| Ambient temperature | -10 ... 60 °C |
| Transferable torque | 17 Nm |
| Product weight | 1,170 g |
| Interface code, actuator | D60A D60B D60C |
| Interface code, motor in | 100A |
| Materials note | Conforms to RoHS |