


Coupling KSE-40-66-D08-D11

Part number: 550997

FESTO

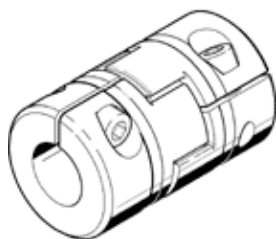

Data sheet

| Feature | Value |
|------------------------|------------------------|
| Holder diameter 1 | 8 mm |
| Holder diameter 2 | 11 mm |
| Size | 40 |
| Assembly position | Any |
| Max. speed | 6,500 1/min |
| Mass moment of inertia | 42.3 kgmm ² |
| Transferable torque | 17 Nm |
| Product weight | 139 g |
| Materials note | Conforms to RoHS |