


Coupling EAMC-30-32-6-6.35

Part number: 551002

FESTO

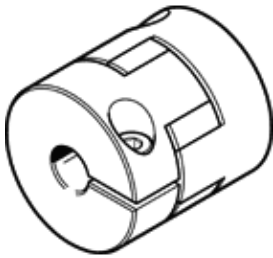

Data sheet

Feature	Value
Holder diameter 1	6 mm
Holder diameter 2	6.35 mm
Size	30
Nominal length	32 mm
Assembly position	Any
Max. speed	8,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	5.87 kgmm ²
Transferable torque	6.5 Nm
Product weight	48 g
Materials note	Conforms to RoHS