


# Silencer U-1/2-BR

Part number: 552422

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

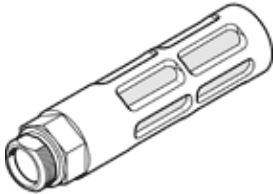

## Data sheet

Feature	Value
Assembly position	Any
Operating pressure MPa	0 ... 1 MPa
Working pressure	0 ... 10 bar
Flow rate to atmosphere	10,600 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Sound pressure level	80 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	75 g
Pneumatic connection	G1/2
Material of silencer insert	PE
Material housing	Aluminum die cast