


Manifold strip MHJ9-PN16

Part number: 553123

FESTO

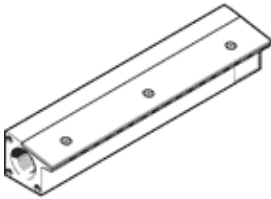

Data sheet

Feature	Value
Grid dimension	10 mm
Max. number of valve positions	16 Versions to customer requirements possible
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Product weight	390 g
Mounting type	With mounting bracket
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 2	Non-ducted
Materials note	Conforms to RoHS
Material manifold	Anodised wrought aluminium alloy