


# Bellows kit DADB-V6-32-S351-375

Part number: 553283

FESTO

For standard cylinders to ISO 15552

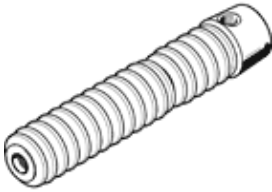

## Data sheet

| Feature                                 | Value  |
|---|--|
| Outside diameter                        | 38 mm  |
| Size                                    | 32   |
| Stroke range                            | 351 ... 375 mm                                   |
| Piston rod extension                    | 114 mm   |
| Design                                  | Round  |
| Assembly position                       | Any  |
| Design structure                        | Bellows kit<br>with ducted exhaust air           |
| Corrosion resistance classification CRC | 3 - High corrosion stress                        |
| PWIS conformity                         | VDMA24364-B2-L                                   |
| Resistance to media                     | Dust<br>Chippings<br>Oils<br>Grease<br>Gasolines |
| Protection class                        | IP54   |
| Ambient temperature                     | -10 ... 80 °C                                    |
| Product weight                          | 92 g   |
| Mounting type                           | slip-on<br>With threaded pin                     |
| Pneumatic connection                    | G1/8   |
| Materials note                          | Conforms to RoHS                                 |
| Material adapter components             | PA-reinforced                                    |
| Material seals                          | NBR  |
| Material bellows                        | NBR  |
| Material threaded pin                   | High alloy steel, non-corrosive                  |