


# Bellows kit DADB-V6-40-S426-475

Part number: 553307

FESTO

For standard cylinders to ISO 15552

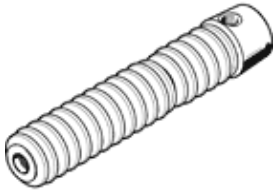

## Data sheet

Feature	Value
Outside diameter	46 mm
Size	40
Stroke range	426 ... 475 mm
Piston rod extension	130 mm
Design	Round
Assembly position	Any
Design structure	Bellows kit with ducted exhaust air
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B2-L
Resistance to media	Dust Chippings Oils Grease Gasolines
Protection class	IP54
Ambient temperature	-10 ... 80 °C
Product weight	144 g
Mounting type	slip-on With threaded pin
Pneumatic connection	G1/8
Materials note	Conforms to RoHS
Material adapter components	PA-reinforced
Material seals	NBR
Material bellows	NBR
Material threaded pin	High alloy steel, non-corrosive