


# Bellows kit DADB-V6-100-S376-425

Part number: 553385

FESTO

For standard cylinders to ISO 15552

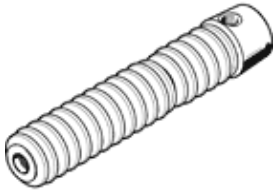

## Data sheet

Feature	Value
Outside diameter	93 mm
Size	100
Stroke range	376 ... 425 mm
Piston rod extension	98 mm
Design	Round
Assembly position	Any
Design structure	Bellows kit with ducted exhaust air
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B2-L
Resistance to media	Dust Chippings Oils Grease Gasolines
Protection class	IP54
Ambient temperature	-10 ... 80 °C
Product weight	321 g
Mounting type	slip-on With threaded pin
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material adapter components	PA-reinforced
Material seals	NBR
Material bellows	NBR
Material threaded pin	High alloy steel, non-corrosive