


Bellows kit DADB-S1-32-S301-350

Part number: 553451

FESTO

For standard cylinders to ISO 6432

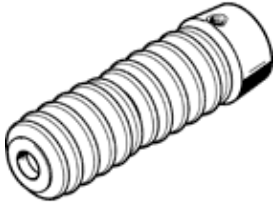

Data sheet

| Feature | Value |
|---|--|
| Outside diameter | 38 mm |
| Size | 32 |
| Stroke range | 301 ... 350 mm |
| Piston rod extension | 113 mm |
| Design | Round |
| Assembly position | Any |
| Design structure | Bellows kit with ducted exhaust air |
| Corrosion resistance classification CRC | 3 - High corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| RSBP classification to CD-0033 | F5a |
| Resistance to media | Dust Chippings Oils Grease Gasolines |
| Protection class | IP54 |
| Ambient temperature | -10 ... 80 °C |
| Product weight | 92 g |
| Mounting type | With threaded pin with internal (female) thread |
| Pneumatic connection | G1/8 |
| Materials note | Conforms to RoHS |
| Material adapter components | PA-reinforced |
| Material seals | NBR |
| Material bellows | NBR |
| Material threaded pin | High alloy steel, non-corrosive |