


# Plastic tubing PEN

Part number: 553769

FESTO

Please observe the minimum order quantity.

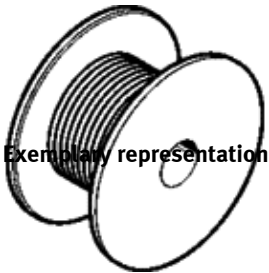

Exemplary representation

## Data sheet

Overall data sheet – Individual values depend upon your configuration.

Feature	Value
Outside diameter	4 ... 16 mm
Inside diameter	2.7 ... 10.8 mm
Temperature dependent working pressure	-0.95 ... 10 bar
Authorization	TÜV
Certificate issuing department	B 013277 0506 00
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
PWIS conformity	VDMA24364-B1/B2-L
Cleanroom class	This product is a static object, active particle generation is not possible when used correctly. Clean product before using it in a cleanroom environment and ensure it is installed correctly.
Ambient temperature	-30 ... 60 °C
Color	blue yellow green neutral Red Black silver white
Shore hardness	D 52 +/-3
Materials note	Conforms to RoHS
Material tubing	PE