


Electrical interface CECX-C-S1

Part number: 553855

FESTO

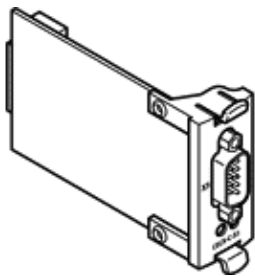

Data sheet

Feature	Value
Corrosion resistance classification CRC	0 - No corrosion stress
Authorization	c UL us - Listed (OL)
Materials note	Contains PWIS substances Conforms to RoHS
Power consumption at system bus	0.2 W
Ambient temperature	5 ... 55 °C
Storage temperature	-40 ... 70 °C
Relative air humidity	10 - 95 %
Safety class	III
Product weight	31 g
Test for insensitivity to vibration	EN 60068-2-6 FC 5 - 9 Hz 3,5 mm 9 - 150 Hz 1g
Test for insensitivity to shock	EN 60068-2-27 EA 15 g, 11 ms (half sine)
Serial interface, type	RS 232
Serial interface, connection technology	9-pin
Serial interface, transmission rate	1200 ... 115000 Bit/s Adjustable via software
Serial interface, electrical isolation	No