


Electrical interface

CECX-S-2S1

Part number: 553978

FESTO

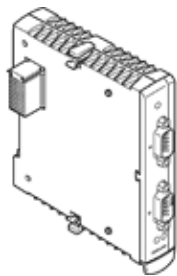

Data sheet

Feature	Value
Corrosion resistance classification CRC	0 - No corrosion stress
Authorization	c UL us - Listed (OL)
Materials note	Contains PWIS substances Conforms to RoHS
Power consumption 5 V	0.4 W
Ambient temperature	5 ... 55 °C
Storage temperature	-40 ... 70 °C
Relative air humidity	10 - 95 %
Protection class	IP20
Safety class	III
Product weight	132 g
Test for insensitivity to vibration	EN 60068-2-6 FC 5 - 9 Hz 3,5 mm 9 - 150 Hz 1g
Test for insensitivity to shock	EN 60068-2-27 EA 15 g, 11 ms (half sine)
Status displays	LED (status)
Serial interface, number	2
Serial interface, type	RS 232
Serial interface, connection technology	Plug Sub-D 9-pin
Serial interface, transmission rate	1200 ... 115200 Bit/s Adjustable via software
Serial interface, electrical isolation	No