

Manifold strip


VABM-C8-12E-G14-14-M1

Part number: 557663

Classic - do not use for new projects

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

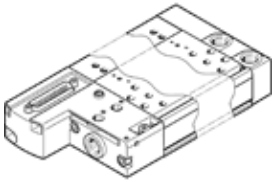

Data sheet

| Feature | Value |
|---|-------------------------|
| Grid dimension | 12 mm |
| Max. number of valve positions | 14 |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Max. tightening torque, valve mounting | 0.6 Nm |
| Max. tightening torque, wall mounting | 5 Nm |
| Product weight | 992 g |
| Pneumatic connection, port 1 | G1/4 |
| Pneumatic connection, port 3 | G1/4 |
| Pneumatic connection, port 5 | G1/4 |
| Materials note | Conforms to RoHS |
| Material manifold | Wrought Aluminum alloy |