


Drive shaft EAMB-24-6-15X21-16X20

Part number: 558036

FESTO

for adapting drives with hollow shaft

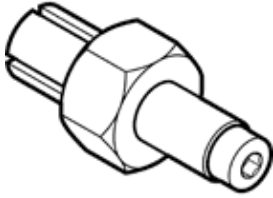

Data sheet

Feature	Value
Holder diameter 1	15 mm
Holder diameter 2	16 mm
Size	80
Nominal length	21 mm
Assembly position	Any
Max. speed	8,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	3.1 kgmm ²
Transferable torque	29 Nm
Product weight	68 g
Materials note	Conforms to RoHS