


# Feed module VMPAL-SP-QS10

Part number: 560951

FESTO

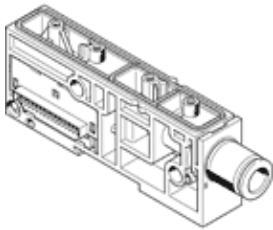

## Data sheet

Feature	Value
Width	23.2 mm
Length	107.3 mm
Integrated function	with electrical interlinking module
Valve manifold structure	Valve sizes can be mixed
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	50 g
Pneumatic connection, port 1	For tubing outside diameter 10 mm
Materials note	Conforms to RoHS
Material supply module	Wrought Aluminum alloy PA-reinforced