


Mains outlet socket NECU-M-PPG5-C1

Part number: 563059

FESTO

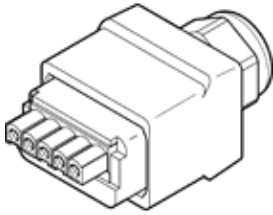

Data sheet

Feature	Value
Based on the standard	EN 61984
Electrical connection	AIDA Push-pull 5-pin pre-assembled Socket / spring-loaded terminal
Plug coding	On contacts 2 and 5
Operating voltage range DC	0 ... 24 V
Acceptable current load at 40°C	16 A
Surge strength	2.5 kV
Permissible cable diameter	9 ... 13 mm
Terminal cross-section	0.75 ... 2.5 mm ²
Protection class	IP65 IP67
Ambient temperature	-40 ... 100 °C
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	Zinc die-casting Nickel plated
Housing color	silver
Material seals	NBR TPE
Material electrical contact	Copper alloy Nickel and gold plated