 



# Flow control plate VABF-S7-F1B5P1-F

Part number: 563401

FESTO

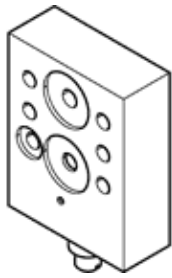

## Data sheet

Feature	Value
Assembly position	Any
Pilot air supply	external Internal
Operating pressure MPa	0 ... 1.2 MPa
Working pressure	0 ... 12 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Mounting type	with through hole
Pilot air port 12	G1/4
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	Flange 1/4 NAMUR port pattern
Pneumatic connection, port 3	G1/4
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium (Ematal coated)
Material seals	NBR