


Electrical sub-base VAVE-L1-1VS2-LP

Part number: 566718

FESTO

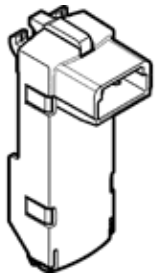

Data sheet

| Feature | Value |
|---|-------------------------|
| Polarity protected | Bipolar |
| Additional functions | Spark arresting |
| Signal status display | LED |
| Nominal operating voltage DC | 24 V 12 V |
| Surge strength | 0.8 kV |
| Degree of contamination | 3 |
| Extended ambient temperature | -5 - 60 °C |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Protection class | IP40 |
| Ambient temperature | -5 ... 50 °C |
| Assembly position | Any |
| Product weight | 1.5 g |
| Electrical connection | 2-pin Plug socket |
| Protective earth connection | Not available |
| Mounting type | Clip |
| Housing color | Black |
| Materials note | Conforms to RoHS |
| Material housing | PA |