


# Manifold strip VABM-B6-E-N14-6

Part number: 568187

FESTO

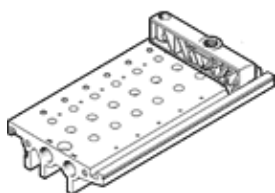

## Data sheet

Feature	Value
Grid dimension	21 mm
Max. number of valve positions	6
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Max. tightening torque, H-rail mounting	1.5 Nm
Max. tightening torque, valve mounting	2 Nm
Max. tightening torque, wall mounting	5 Nm
Product weight	530 g
Auxiliary pilot air port 12/14	NPT1/8-27
Pneumatic connection, port 1	NPT1/4-18
Pneumatic connection, port 3	NPT1/4-18
Materials note	Free of copper and PTFE Conforms to RoHS
Material manifold	Wrought Aluminum alloy