


Electrical sub-base CAPC-F1-E-M12

Part number: 570042

FESTO

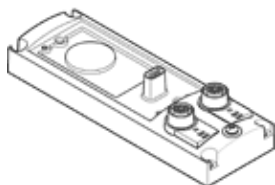

Data sheet

| Feature | Value |
|---|-------------------------------|
| Dimensions W x L x H | 50 mm x 148 mm x 28 mm |
| Fieldbus interface | 2 x M12 socket, 5 pin |
| Operating voltage range DC | 18 ... 30 V |
| Max. power supply | 4 A |
| Nominal operating voltage DC | 24 V |
| Authorization | c UL us - Listed (OL) |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| Storage temperature | -20 ... 70 °C |
| PWIS conformity | VDMA24364-B2-L |
| Protection class | IP65 IP67 |
| Ambient temperature | -5 ... 50 °C |
| Product weight | 85 g |
| Cable length | 20 m |
| Materials note | Conforms to RoHS |
| Material housing | PA |