


Linear gantry

DHSL-25-2EGC120TB-DGEA40

Part number: 574535

FESTO

Please click above on symbol FAX request, to obtain a non-binding offer to fulfill your requirements.

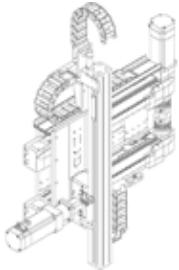

Data sheet

| Feature | Value |
|--|--|
| Assembly | Linear gantry 25 |
| Effective load | 0 ... 25 kg |
| Drive unit, Z axis | DGEA-40 |
| Drive system, Z axis | Electrical toothed belt actuator |
| Intermediate position, Z axis | Any |
| Stroke, Z axis | 0 ... 1,000 mm |
| Repetition accuracy in the end position, Z axis | ± 0,05 mm |
| Repetition accuracy in the intermediate position, Z axis | ± 0,05 mm |
| Drive unit, Y axis | 2x EGC-120-TB |
| Drive system, Y axis | Electrical Toothed belt actuator with ball bearing guide 2x |
| Intermediate position, Y axis | Any |
| Stroke, Y axis | 0 ... 8,500 mm |
| Repetition accuracy in the end position, Y axis | ± 0,08 mm |
| Repetition accuracy in the intermediate position, Y axis | ± 0,08 mm |