


Plug NECU-S1W9-C2-ACO

Part number: 574588

FESTO

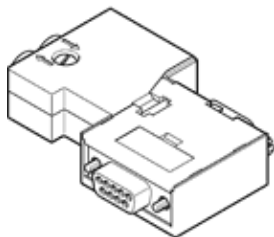

Data sheet

Feature	Value
Mounting type	4-40 UNC-2B
Product weight	59 g
Fieldbus interface	Sub-D, 9-pin, socket
Electrical connection 1	Socket, sub-D, 9-pin
Electrical connection 2	Screw terminal, can be screened
Baud rate	1 Mbit/s
Permissible cable diameter	8 mm 8 mm
Terminal cross-section	0.14 ... 0.5 mm ²
Protection class	IP20
Ambient temperature	-20 ... 70 °C
Relative air humidity	75% at 25°C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	Reinforced PC