


# Bus interface CDPX-F-CO

Part number: 575301

FESTO

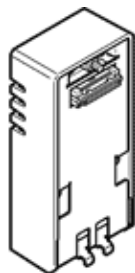

## Data sheet

Feature	Value
Depth	24 mm
Height	91 mm
Length	41 mm
Authorization	C-Tick c UL us - Listed (OL)
CE symbol (see declaration of conformity)	according to EU-EMV guideline in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
PWIS conformity	VDMA24364 zone III
Storage temperature	-20 ... 70 °C
Relative air humidity	5 - 85 % non-condensing
Protection class	IP20
Ambient temperature	0 ... 50 °C
Product weight	150 g
Materials note	Conforms to RoHS
Fieldbus interface	CANopen
Fieldbus interface, connection technology	Plug Sub-D 9-pin
Fieldbus interface, transmission rate	9,6 kbit/s bis 1 Mbit/s