


# Plug NECU-M-S-A12G4-IS

Part number: 575719

FESTO

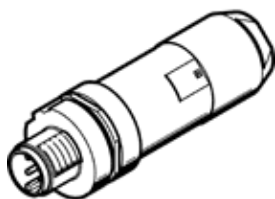

## Data sheet

Feature	Value
Based on the standard	EN 61076-2-101
Assembly position	Any
Product weight	38 g
Electrical connection	4-pin Cage clamp terminal M12x1 Plug straight
Plug coding	A
Operating voltage range DC	0 ... 30 V
Acceptable current load at 40°C	4 A
Permissible cable diameter	4 ... 8 mm
Terminal cross-section	0.14 ... 0.5 mm <sup>2</sup>
Protection class	IP65 IP67
Ambient temperature	-40 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	0 - No corrosion stress
Material housing	Zinc die-casting Nickel plated
Material electrical contact	Bronze Gold plated