


Plug NECC-S1G9-C2-M

Part number: 576031

FESTO

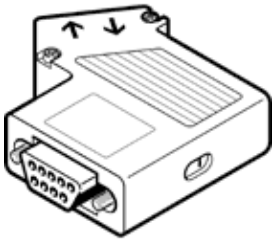

Data sheet

Feature	Value
Height	39,4 mm
Length	58 mm
Product weight	24 g
Fieldbus interface	Sub-D, 9-pin, socket
Electrical connection	9-pin / 9-pin Sub-D/screw terminal
Baud rate	1 Mbit/s
Permissible cable diameter	8 mm 8 mm
Protection class	IP40
Ambient temperature	-20 ... 70 °C
CE symbol (see declaration of conformity)	according to EU low voltage guideline
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Corrosion resistance classification CRC	1 - Low corrosion stress