


# Multi-socket KDVF-8

Part number: 7563

FESTO

For multi-tube connection of plastic tubing with 2, 3 and 4 mm ID.

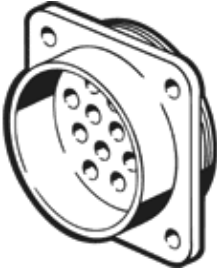

## Data sheet

Feature	Value
Nominal size	4 mm
Working pressure	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	36 g
Max. number of connections	8
Pneumatic connection	PK-2 PK-3 PK-4
Color	Grey
Materials note	Conforms to RoHS