


Vertical pressure supply plate

VABF-S4-2-P1A14-N18

Part number: 8000694

FESTO

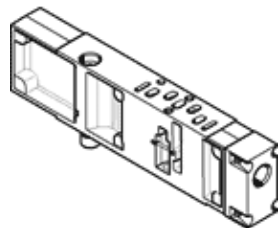

Data sheet

Feature	Value
Width	18 mm
Based on the standard	ISO 15407-2
Assembly position	Any
Pneumatic vertical stacking	Alternative pressure supply for 1 and 14
Operating pressure MPa	1 MPa
Working pressure	10 bar
Standard nominal flow rate	430 l/min
CE symbol (see declaration of conformity)	according to EU low voltage guideline
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Ambient temperature	-5 ... 50 °C
Product weight	140 g
Vertical stacking type of mounting	on manifold block on individual subbase
Pneumatic connection, port 1	1/8 NPT
Materials note	Conforms to RoHS
Material housing	Aluminum die cast