


Manifold strip VABM-L1-18W-G38-20-M-G

Part number: 8004925

FESTO

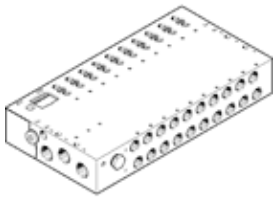

Data sheet

| Feature | Value |
|---|-------------------------------|
| Grid dimension | 19 mm |
| Assembly position | Any |
| Max. number of valve positions | 20 |
| Authorization | c UL us - Recognized (OL) |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Storage temperature | -20 ... 60 °C |
| Product weight | 4,201 g |
| Auxiliary pilot air port 12/14 | G1/8 |
| Pilot exhaust port 82/84 | G1/8 |
| Pneumatic connection, port 1 | G3/8 |
| Pneumatic connection, port 2 | G1/4 |
| Pneumatic connection, port 3 | G3/8 |
| Pneumatic connection, port 4 | G1/4 |
| Pneumatic connection, port 5 | G3/8 |
| Materials note | Conforms to RoHS |
| Material manifold | Wrought Aluminum alloy |