


Push-in/threaded L-fitting QSL-G1/4-8-C35-50

Part number: 8005395

FESTO

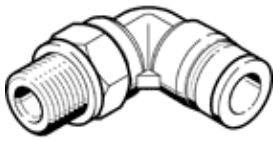

Data sheet

Feature	Value
Size	Standard
Nominal size	3.5 mm
Type of seal on screw-in stud	Sealing ring
Assembly position	Any
Container size	50
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1
Ambient temperature	-20 ... 80 °C
Max. tightening torque	15 Nm
Product weight	1,370 g
Pneumatic connection	Male thread G1/4 For tubing outside diameter 8 mm
color of release ring	Black
Materials note	Conforms to RoHS
Materials information, housing	Brass Nickel plated
Materials information for thread seal	NBR
Materials information for tubing seal	NBR
Hose clamping segment material data	High alloy steel, non-corrosive