


# Supply plate

## VABF-B10-25-P1A4-G14-P3

Part number: 8026319

FESTO

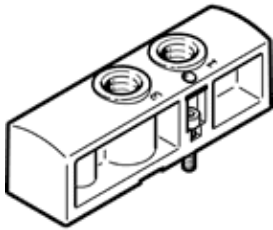

### Data sheet

Feature	Value
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque	3 Nm
Product weight	80 g
Mounting type	with through hole
Pneumatic connection, port 1	G1/4
Materials note	Conforms to RoHS
Material supply plate	Aluminum die cast