


Solenoid coil VACN-N-A1-1

Part number: 8029144

★ Core product range

for armature system FN, connection pattern type A, according to EN 175 301, 24 V DC.

FESTO

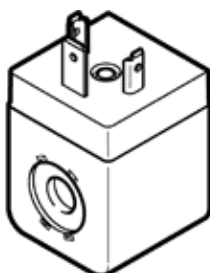

Data sheet

Feature	Value
Type of actuation	electrical
Assembly position	Any
Duty cycle	100 %
Insulation class	F
Enamelled wire insulation class	F
Characteristic coil data	24 V DC: 0.7 W
Permissible voltage fluctuation	+/- 10 %
Maritime classification	see certificate
Certificate issuing department	DNV TAA000011J
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Protection class	IP65
Ambient temperature	-20 ... 60 °C
Product weight	95 g
Electrical connection	Plug pattern type A to EN 175301-803 Per DIN EN 175301-803
Mounting type	With knurled nut
Materials note	Conforms to RoHS
Material housing	Plastic Steel
Material electrical contact	Brass
Material winding	Copper