


Elbow fitting NPFC-L-R34-G34-MF

Part number: 8030220

FESTO

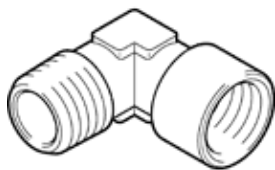

Data sheet

Feature	Value
Material threaded fitting	Nickel-plated brass
Container size	10
Working pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:--]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	131.7 g
Pneumatic connection, port 1	R3/4
Pneumatic connection, port 2	G3/4
Materials note	Conforms to RoHS