


Y-fitting
NPFC-Y-R14-2G14-MFF
Part number: 8030232

FESTO

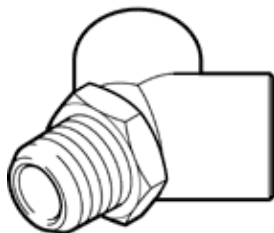

Data sheet

Feature	Value
Material threaded fitting	Nickel-plated brass
Container size	10
Working pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:--:--]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	40.8 g
Pneumatic connection, port 1	R1/4
Pneumatic connection, port 2	G1/4
Materials note	Conforms to RoHS