


# T fitting

## NPFC-T-G14-2R14-FMM

Part number: 8030256

FESTO

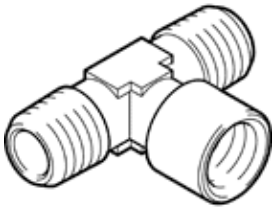

### Data sheet

Feature	Value
Material threaded fitting	Nickel-plated brass
Container size	10
Working pressure	-0.95 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 ... 150 °C
Product weight	40.3 g
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	R1/4
Materials note	Conforms to RoHS