


Double nipple NPFC-D-R12-R34-M

Part number: 8030287

FESTO

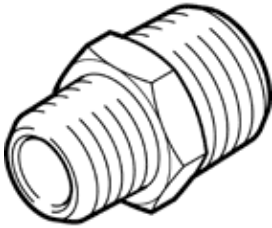

Data sheet

| Feature | Value |
|---|---|
| Material threaded fitting | Nickel-plated brass |
| Container size | 10 |
| Working pressure | -0.95 ... 50 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [-:--] |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -20 ... 150 °C |
| Product weight | 68.5 g |
| Pneumatic connection, port 1 | R1/2 |
| Pneumatic connection, port 2 | R3/4 |
| Materials note | Conforms to RoHS |