


# Parallel kit EAMM-U-145-D80-126AA-188

Part number: 8059069

FESTO

Suitable for electric drives.

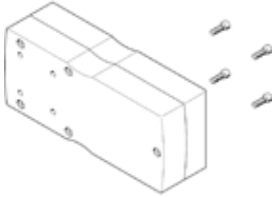

## Data sheet

Feature	Value
Size	145
Assembly position	Any
Max. speed	4,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	-10 ... 60 °C
Mass moment of inertia	2,270 kgmm <sup>2</sup>
No-load driving torque	2 Nm
Transferable torque	9.5 Nm
Product weight	12,000 g
Interface code, actuator	D80
Interface code, motor in	126AA
Materials note	Conforms to RoHS