


coupling socket NPHS-D6-P-G18

Part number: 8059266

FESTO

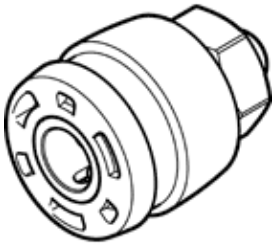

Data sheet

Feature	Value
Nominal size	5 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Standard nominal flow rate	875 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	3.5 Nm
Tolerance for nominal tightening torque	± 10 %
Product weight	94 g
Pneumatic connection, port 1	Male thread G1/8
Materials note	Conforms to RoHS