


# coupling socket NPHS-D6-P-G14

Part number: 8059267

FESTO

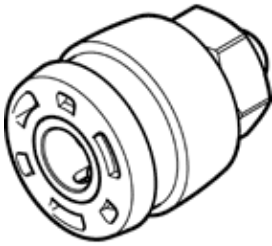

## Data sheet

Feature	Value
Nominal size	7.8 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Standard nominal flow rate	1,916 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Nominal tightening torque	11 Nm
Tolerance for nominal tightening torque	± 10 %
Product weight	95 g
Pneumatic connection, port 1	Male thread G1/4
Materials note	Conforms to RoHS