


# coupling socket NPHS-D6-P-BC9

Part number: 8059274

FESTO

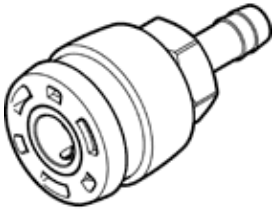

## Data sheet

Feature	Value
Nominal size	7 mm
Operating pressure complete temperature range	-0.95 ... 10 bar
Standard nominal flow rate	1,448 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-10 ... 60 °C
Product weight	95 g
Pneumatic connection, port 1	for barbed connector internal diameter 9 mm
Materials note	Conforms to RoHS