 



Vacuum filter

OAFF-G3-7

Part number: 8068945

FESTO

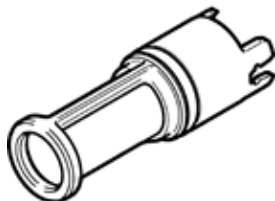

Data sheet

Feature	Value
Grade of filtration	40 µm
Container size	10
Operating pressure MPa	-95 ... 0 kPa
Working pressure	-0.95 ... 0 bar
Operating pressure	-13.775 ... 0 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
PWIS conformity	VDMA24364-B1/B2-L
Product weight	1.5 g
Mounting type	slip-on Detenting
Materials note	Conforms to RoHS
Material seals	NBR
Material filter	Mesh PA
Material housing	POM
Ejector pulse suitability	0.7 MPa 7 bar
Ejector pulse suitability (psi)	101.5 psi