


Operator unit CDSB-A1

Part number: 8070984

★ Core product range

FESTO

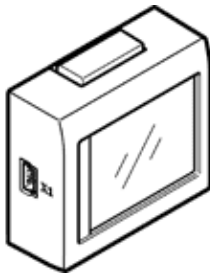

Data sheet

| Feature | Value |
|--|---|
| Max. line length | 3 m |
| User memory | 3 GB |
| Display | TFT color |
| Display property | Touchscreen |
| Display size | 1.77" |
| Operating voltage range DC | 4.5 ... 5.5 V |
| Display resolution | 128x160 Pixel |
| Authorization | RCM Mark |
| KC mark | KC-EMV |
| CE symbol (see declaration of conformity) | according to EU-EMV guideline in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK instructions for EMC To UK RoHS instructions |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -20 ... 70 °C |
| Relative air humidity | non-condensing Max. 95% at 60°C |
| Protection class | IP20 |
| Ambient temperature | 0 ... 60 °C |
| Product weight | 36.6 g |
| USB interface, connection technology | USB 2.0 type B mini |
| Materials note | Conforms to RoHS |
| Material housing | PA6 reinforced |
| Area of application | Only with CMMT, CPX-E-CEC |
| Dimensions W x L x H | 50 mm x 45 mm x 19,6 mm |